


Flansa oscilanta SNGB-160

Numar piesa: 34547

FESTO

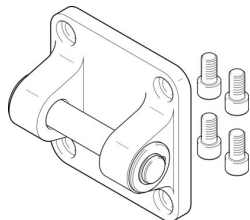

Fisa de date

Caracteristica	Valoare
Dimensiune	160
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...90 °C
Greutate produs	3445 g
Nota privind materialele	Conform RoHS
Material fixare	Aluminiu turnat sub presiune
Material bolt	Otel galvanizat
Material rulment	Material plastic
Material saiba	Otel galvanizat
Material suruburi	Otel galvanizat
Material siguranta	Otel cu arc, galvanizat