


Placa interm. regulator LR-ZP-A-D-3

Numar piesa: 35971

FESTO

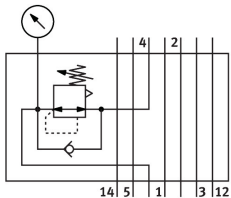

Fisa de date

Caracteristica	Valoare
Pe baza standardului	ISO 5599-1
Functie integrata	Regulator de presiune
Structura constructiva	Piston
Domeniu de reglare a presiunii	0.05 MPa...1.2 MPa 0.5 bar...12 bar 7.25 psi...174 psi
Presiune de intrare 1	14 bar 1.4 MPa 203 psi
Autorizare	UL - Recunoscut (OL)
Conformitatea LABS	VDMA24364 zona III
Greutate produs	1220 g
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material carcasa	Aluminiu turnat sub presiune Otel