 



Ventil electromagnetic JMFH-5-PK-3

Numar piesa: 4447

FESTO

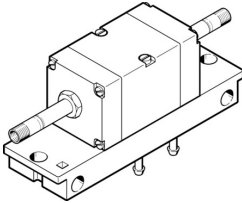

Fisa de date

Caracteristica	Valoare
Funcție de ventil	5/2 bistabil
Debit nominal standard (normalizat conform DIN 1343)	105 l/min
Racord pneumatic de lucru	PK-3
Presiune de lucru	2 bar...8 bar
Structura constructiva	Scaun-farfurie
Latimea nominala	2.5 mm
Principiul de etansare	slab
Timp de comutare	13 ms
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:...]]
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura medie	0 °C...60 °C
Temperatura ambianta	0 °C...40 °C
Greutate produs	380 g
Tipul de montare	pe placa de racordare pe cadrul de montare cu orificiu de trecere optional:
Conector pneumatic 1	PK-3
Conexiune pneumatica 2	PK-3
Conector pneumatic 3	PK-3
Conexiune pneumatica 4	PK-3
Conexiune pneumatica 5	PK-3
Nota privind materialele	Conform RoHS
Materialul placii de racordare	Aluminiu anodizat
Material garnituri	NBR
Material carcasa	Aluminiu anodizat