 



Filtru EMC CAMF-C5-FC

Numar piesa: 4825847

FESTO

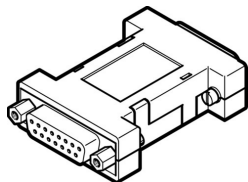

Fisa de date

Caracteristica	Valoare
Domeniu de tensiune de lucru CC	0 V...30 V
Tensiune nominala de functionare CC	24 V
Domeniu de tensiune de lucru CA	0 V...30 V
Tensiunea nominala de functionare CA	24 V
Conformitatea LABS	VDMA24364-B2-L
Tip de protectie	IP30
Nota privind tipul de protectie	in stare asamblata
Temperatura ambianta	-40 °C...80 °C
Nota privind materialele	Conform RoHS
Conector electric 1, functie	Partea fieldbus
Conector electric 1, design	unghiular
Conexiune electrica 1, tip de conectare	Priza
Conexiune electrica 1, iesire de cablu	drept
Conexiune electrica 1, tehnologie de conectare	Sub-D
Conexiune electrica 1, numar de pini/fire	15
Conexiune electrica 1, pini/fire ocupate	8
Conexiune electrica 2, functie	Pagina de control
Conexiune electrica 2, design	unghiular
Conectorare electrica 2, tip de racord	Stecher
Conexiune electrica 2, iesire de cablu	drept
Conexiune electrica 2, tehnologie de conectare	Sub-D
Conector electric 2, numar de pini/conductoare	15
Conector electric 2, pini/conductoare alocate	8
Conexiune electrica 2, tip de montare	2x surub 4-40 UNC-2A
Protocol	HIPERFACE
Culoarea carcasei	argint
Material carcasa	Plastic metalizat