


**Manometru**  
**MA-50-0,25-R1/4-MPA-E-RG**  
Numar piesa: 526780

**FESTO**

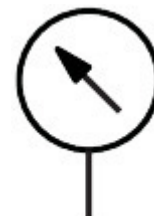

**Fisa de date**

| Caracteristica                              | Valoare                                                                                                      |
|---------------------------------------------|--------------------------------------------------------------------------------------------------------------|
| Interval de afisare                         | 0 MPa...0.25 MPa                                                                                             |
| Conform cu standardul                       | EN 837-1                                                                                                     |
| Dimensiune nominala, manometru              | 50                                                                                                           |
| Protectie la explozie                       | Respectati informatiile din certificat<br>Zona 1 (ATEX)<br>Zona 2 (ATEX)<br>Zona 21 (ATEX)<br>Zona 22 (ATEX) |
| Structura constructiva                      | Manometru cu tub Bourdon                                                                                     |
| Tipul de montare                            | Instalarea liniei                                                                                            |
| Mediu de operare                            | Gaze inerte<br>lichide neutre                                                                                |
| Nota referitoare la mediul de lucru/comanda | fara acetilena<br>fara oxigen                                                                                |
| Presiune de lucru                           | 0 MPa...0.25 MPa<br>0 bar...2.5 bar<br>0 psi...36.25 psi                                                     |
| Factor de incarcare alternanta              | 0.66                                                                                                         |
| Clasa de precizie de masurare               | 2,5                                                                                                          |
| Tip de protectie                            | IP43                                                                                                         |
| Temperatura medie                           | -20 °C...60 °C                                                                                               |
| Temperatura ambianta                        | -20 °C...60 °C                                                                                               |
| Conformitatea LABS                          | VDMA24364-B1/B2-L                                                                                            |
| Nota privind materialele                    | Conform RoHS                                                                                                 |
| Pozitie de conectare                        | Partea din spate, centrat                                                                                    |
| Conexiune pneumatica                        | R1/4                                                                                                         |
| Materiale care intra in contact cu mediul   | Alama                                                                                                        |
| Material pivot de insurubare                | Alama                                                                                                        |
| Material carcasa                            | ABS                                                                                                          |
| Material vizor                              | PMMA                                                                                                         |
| Culoarea carcasei                           | negru                                                                                                        |
| Greutate produs                             | 75 g                                                                                                         |

| Caracteristica | Valoare                       |
|----------------|-------------------------------|
| Scala          | Scara unica<br>MPa (exterior) |