


# Combinatie filtre fine LFMBA-1/2-D-MAXI-DA

Numar piesa: 532870

**FESTO**

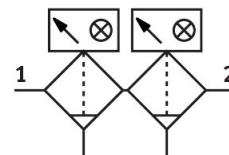

## Fisa de date

| Caracteristica                        | Valoare                                                      |
|---------------------------------------|--------------------------------------------------------------|
| Dimensiune                            | Maxi                                                         |
| Seria                                 | D                                                            |
| Pozitie de instalare                  | vertical +/- 5°                                              |
| Finete de filtrare                    | 0.01 µm                                                      |
| Eficienta filtru                      | 99.9999 %                                                    |
| Purjare a condensului                 | rotire manuala                                               |
| Structura constructiva                | Filtru de fibre                                              |
| Cantitate max. de condens             | 80 ml                                                        |
| Protectie pahar                       | Cos metalic de protectie                                     |
| Presiune de lucru                     | 0.1 MPa...1.6 MPa<br>1 bar...16 bar<br>14.5 psi...232 psi    |
| Mediu de operare                      | Aer comprimat conform ISO 8573-1:2010 [6:8:4]<br>Gaze inerte |
| Conformitatea LABS                    | VDMA24364-B1/B2-L                                            |
| Clasa de puritate a aerului la iesire | Aer comprimat conform ISO 8573-1:2010 [1:7:2]<br>Gaze inerte |
| Temperatura medie                     | 1.5 °C...60 °C                                               |
| Continut de ulei rezidual             | 0.01 mg/m³                                                   |
| Temperatura ambianta                  | -10 °C...60 °C                                               |
| Greutate produs                       | 2362 g                                                       |
| Tipul de montare                      | Instalarea liniei<br>cu accesorii                            |
| Conector pneumatic 1                  | G1/2                                                         |
| Conexiune pneumatica 2                | G1/2                                                         |
| Nota privind materialele              | Conform RoHS                                                 |
| Material filtru                       | Fibra de borosilicat                                         |
| Material carcasa                      | Zinc turnat sub presiune<br>PC                               |