


# Combinatie filtre fine LFMBA-3/4-D-MAXI-DA-A

Numar piesa: 532881

**FESTO**

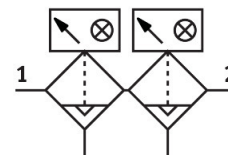

## Fisa de date

| Caracteristica                        | Valoare                                                       |
|---------------------------------------|---------------------------------------------------------------|
| Dimensiune                            | Maxi                                                          |
| Seria                                 | D                                                             |
| Pozitie de instalare                  | vertical +/- 5°                                               |
| Finete de filtrare                    | 0.01 µm                                                       |
| Eficienta filtru                      | 99.9999 %                                                     |
| Purjare a condensului                 | complet automat                                               |
| Structura constructiva                | Filtru de fibre                                               |
| Cantitate max. de condens             | 80 ml                                                         |
| Protectie pahar                       | Cos metalic de protectie                                      |
| Presiune de lucru                     | 0.15 MPa...1.2 MPa<br>1.5 bar...12 bar<br>21.75 psi...174 psi |
| Mediu de operare                      | Aer comprimat conform ISO 8573-1:2010 [6:8:4]<br>Gaze inerte  |
| Conformitatea LABS                    | VDMA24364-B1/B2-L                                             |
| Clasa de puritate a aerului la iesire | Aer comprimat conform ISO 8573-1:2010 [1:7:2]<br>Gaze inerte  |
| Temperatura medie                     | 1.5 °C...60 °C                                                |
| Continut de ulei rezidual             | 0.01 mg/m³                                                    |
| Temperatura ambianta                  | -10 °C...60 °C                                                |
| Greutate produs                       | 2362 g                                                        |
| Tipul de montare                      | Instalarea liniei<br>cu accesorii                             |
| Conector pneumatic 1                  | G3/4                                                          |
| Conexiune pneumatica 2                | G3/4                                                          |
| Nota privind materialele              | Conform RoHS                                                  |
| Material filtru                       | Fibra de borosilicat                                          |
| Material carcasa                      | Zinc turnat sub presiune<br>PC                                |