


Stecher
FBS-RJ45-8-GS
Numar piesa: 534494

FESTO

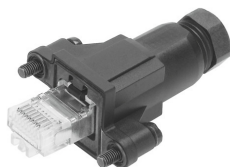

Fisa de date

Caracteristica	Valoare
Latime	33 mm
Inaltime	41 mm
Lungime	20 mm
Greutate produs	15 g
Specificatie cablu Ethernet	Tip: CAT.5 Diametrul unui singur fir: 0,89 - 0,99 mm AWG 24-26 flexibil
Protectie contra atingerii directe si indirecte	PELV
Diametrul admisibil al cablului	4 mm...5.4 mm
Tip de protectie	IP65 IP67 conform IEC 60529
Temperatura ambianta	-5 °C...60 °C
Temperatura de depozitare	-20 °C...70 °C
Umiditate relativa	0 - 90 % fara condensare
Conformitatea LABS	VDMA24364-B2-L
Material carcasa	Ranforsat cu PA
Material suruburi	Otel
Material garnituri	NBR