


# Compensator de moment FKC-32

Numar piesa: 538961

FESTO

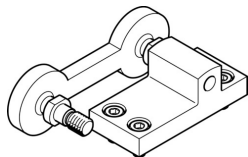

## Fisa de date

| Caracteristica                                                   | Valoare                      |
|------------------------------------------------------------------|------------------------------|
| Dimensiune                                                       | 32                           |
| Abatere radiala +/-                                              | 2.5 mm                       |
| Clasa de rezistenta la coroziune KBK                             | 1 - stres redus la coroziune |
| Conformitatea LABS                                               | VDMA24364-B1/B2-L            |
| Temperatura ambianta                                             | -10 °C...60 °C               |
| Sarcina maxima admisibila pe termen scurt in directia fortei +/- | 3000 N                       |
| Sarcina maxim admisibila pe termen lung in directia fortei +/-   | 1400 N                       |
| Greutate produs                                                  | 122.3 g                      |
| Nota privind materialele                                         | Conform RoHS                 |
| Material articulatie                                             | Ranforsat cu PA              |
| Material fus sferic                                              | otel inalt aliat             |
| Material placa                                                   | Aliaj de aluminiu forjat     |