


Compensator de moment FKC-40

Numar piesa: 538962

FESTO

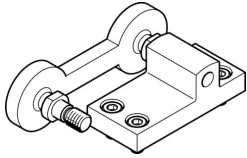

Fisa de date

Caracteristica	Valoare
Dimensiune	40
Abatere radiala +/-	2.5 mm
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-10 °C...60 °C
Sarcina maxima admisibila pe termen scurt in directia fortei +/-	3000 N
Sarcina maxim admisibila pe termen lung in directia fortei +/-	1400 N
Greutate produs	180.2 g
Nota privind materialele	Conform RoHS
Material articulatie	Ranforsat cu PA
Material fus sferic	otel inalt aliat
Material placa	Aliaj de aluminiu forjat