


Fixare oscilanta SBN-40

Numar piesa: 539925

FESTO

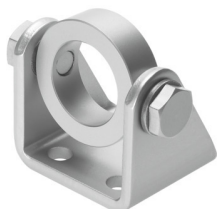

Fisa de date

Caracteristica	Valoare
Dimensiune	40
Pozitie de instalare	orice
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-40 °C...90 °C
Greutate produs	593 g
Nota privind materialele	Conform RoHS
Material inel de fixare	Aliaj de aluminiu forjat anodizat
Material fixare	Otel galvanizat
Material bolt	Otel galvanizat
Material rulment	Bronz
Material suruburi	Otel, galvanizat
Material echer	Otel