


## Fixare oscilanta SBN-20/25

Numar piesa: 539927

FESTO

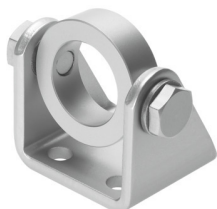

### Fisa de date

| Caracteristica                       | Valoare                              |
|--------------------------------------|--------------------------------------|
| Dimensiune                           | 20/25                                |
| Pozitie de instalare                 | orice                                |
| Clasa de rezistenta la coroziune KBK | 1 - stres redus la coroziune         |
| Conformitatea LABS                   | VDMA24364-B1/B2-L                    |
| Temperatura ambianta                 | -40 °C...90 °C                       |
| Greutate produs                      | 238 g                                |
| Nota privind materialele             | Conform RoHS                         |
| Material inel de fixare              | Aliaj de aluminiu forjat<br>anodizat |
| Material fixare                      | Otel galvanizat                      |
| Material bolt                        | Otel galvanizat                      |
| Material rulment                     | Bronz                                |
| Material piulita                     | Otel, galvanizat                     |
| Material suruburi                    | Otel, galvanizat                     |
| Material echer                       | Otel                                 |