


Set axial EAMM-A-D32-42A

Numar piesa: 543148

FESTO

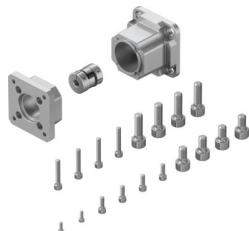

Fisa de date

Caracteristica	Valoare
Lungime nominala	48 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	0.28 kgmm ²
Cuplu transmisibil	1.1 Nm
Greutate produs	140 g
Cod de interfata actuator	D32 D32C
Codul interfetei motor In	42A
Nota privind materialele	Conform RoHS