


Set axial EAMM-A-D60-70A

Numar piesa: 543161

FESTO

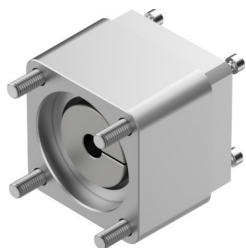

Fisa de date

Caracteristica	Valoare
Lungime nominala	63.2 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	17 Nm
Greutate produs	750 g
Cod de interfata actuator	D60 D60C
Codul interfetei motor In	70A
Nota privind materialele	Conform RoHS