


Ventil siguranta vacuum ISV-M6

Numar piesa: 545997

FESTO

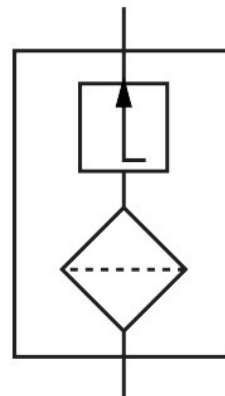

Fisa de date

Caracteristica	Valoare
Dimensiune	M6
Capacitate de impuls de cadere	0.8 MPa 8 bar
Pozitie de instalare	orice
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar
Debit volumetric de aspiratie necesar, la -0,05 MPa (-0,5 bari, -7,25 psi)	2 l/min
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:::]
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-10 °C...60 °C
Greutate produs	14 g
Tipul de montare	insurubabil
Conector pneumatic 1	M6
Conexiune pneumatica 2	M6
Material arc	otel aliaj inalt
Material filtru	Bronz sinterizat
Material carcasa	Aliaj de aluminiu forjat
Material plutitor	POM