


Amortizor de soc DYSW-12-20-Y1F

Numar piesa: 548075

FESTO

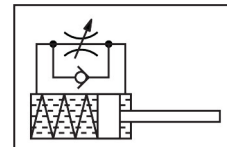

Fisa de date

Caracteristica	Valoare
Dimensiune	12
Cursa	20 mm
Amortizare	autoreglare caracteristica slaba
Pozitie de instalare	orice
Detectarea pozitiei	fara
Viteza max. de impact	3 m/s
Timp de resetare la temperatura camerei	0.3 s
Timp de resetare la temperatura ambientala minima	1 s
Mod de functionare	cu apasare cu simpla actiune
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-10 °C...80 °C
Lungime de amortizare	20 mm
Forta max. de ridicare	1000 N
Consumul max. de energie pe cursa	12 J
Consum max. de energie pe ora	41000 J
Energie reziduala max.	0.05 J
Forta de restabilire	5 N
Forta minima de insertie	35 N
Greutate produs	91 g
Interval de masa	30 kg
Tipul de montare	cu piulita de blocare
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material carcasa	Otel galvanizat
Material tija de piston	otel aliaj inalt