


Obturator CPX-M-AK-C

Numar piesa: 548753

FESTO

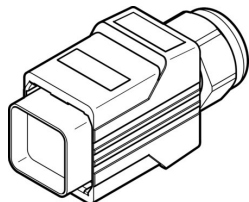

Fisa de date

Caracteristica	Valoare
Latime	30 mm
Inaltime	58 mm
Lungime	22 mm
Autorizare	UL94 V0
Greutate produs	54 g
Tip de protectie	IP65 IP67 in stare asamblata conform IEC 60529
Temperatura ambianta	-5 °C...50 °C
Temperatura de depozitare	-40 °C...70 °C
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Material carcasa	Zinc turnat sub presiune nichelat
Material garnituri	NBR
Umiditate relativa	5 - 90 % fara condensare