


Aparatoare CPX-M-AK-M

Numar piesa: 548754

FESTO

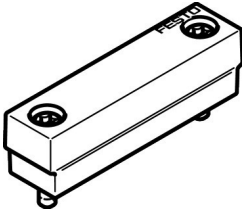

Fisa de date

Caracteristica	Valoare
Latime	11,5 mm
Inaltime	13 mm
Lungime	49 mm
Greutate produs	15 g
Tip de protectie	IP65 IP67 in stare asamblata conform IEC 60529
Temperatura ambianta	-5 °C...50 °C
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Clasa de rezistenta la coroziune KBK	0 - nu este afectat de coroziune
Material suruburi	Otel galvanizat
Material garnituri	NBR
Material capac	Aluminiu turnat sub presiune
Umiditate relativa	5 - 90 % fara condensare