


Bara de racordare VABM-C7-12W-G18-4

Numar piesa: 549650

FESTO

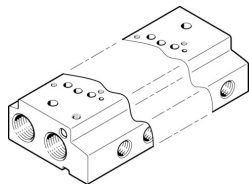

Fisa de date

Caracteristica	Valoare
Numarul max. de pozitii de ventil	4
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Greutate produs	122 g
Conexiune aer de control 12	M3
Conector pneumatic 1	G1/8
Conexiune pneumatica 2	M7
Conector pneumatic 3	G1/8
Nota privind materialele	Conform RoHS
Material bara de racordare	Aliaj de aluminiu forjat