


## Bara de racordare VABM-C7-12G-G18-4

Numar piesa: 552663

**FESTO**

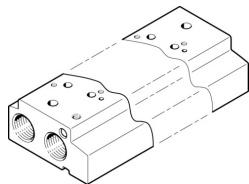

### Fisa de date

| Caracteristica                       | Valoare                                      |
|--------------------------------------|----------------------------------------------|
| Numarul max. de pozitii de ventil    | 4                                            |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS                   | VDMA24364-B2-L                               |
| Greutate produs                      | 126 g                                        |
| Conexiune aer de control 12          | M3                                           |
| Conector pneumatic 1                 | G1/8                                         |
| Conector pneumatic 3                 | G1/8                                         |
| Nota privind materialele             | Conform RoHS                                 |
| Material bara de racordare           | Aliaj de aluminiu forjat                     |