


Bara de racordare VABM-C7-12G-G18-8

Numar piesa: 552667

FESTO

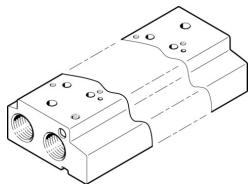

Fisa de date

Caracteristica	Valoare
Numarul max. de pozitii de ventil	8
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Greutate produs	210 g
Conexiune aer de control 12	M3
Conector pneumatic 1	G1/8
Conector pneumatic 3	G1/8
Nota privind materialele	Conform RoHS
Material bara de racordare	Aliaj de aluminiu forjat