
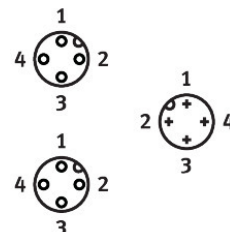


Conector rapid tip T NEDU-M12D4-M12T4-IS

Numar piesa: 562248

FESTO

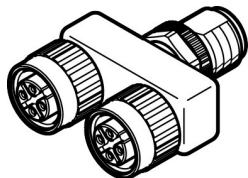

Fisa de date

Caracteristica	Valoare
Pe baza standardului	EN 61076-2-101
Protectie la explozie	Respectati informatiile din certificat Zona 1 (ATEX) Zona 2 (ATEX) Zona 21 (ATEX) Zona 22 (ATEX)
Frecventa de conectare	100
Tipul de montare	insurubabil
Greutate produs	25.5 g
Conector electric	4 pini / 4 pini / 4 pini Codificat A / Codificat A / Codificat A Priza / Priza / Stecher M12x1 / M12x1 / M12x1
Domeniu de tensiune de lucru CC	0 V...30 V
Tip de protectie	IP65 IP67
Temperatura ambianta	-25 °C...85 °C
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Clasa de rezistenta la coroziune KBK	3 - stres intens de coroziune
Material carcasa	ranforsat cu TPE-U(PU) Zinc turnat sub presiune
Material piulita olandeza	ranforsat cu PA
Material garnituri	FPM
Material contacte de cuplare	Aliaj de cupru placat cu aur