


# Flansa oscilanta SNGB-200-B

Numar piesa: 562455

FESTO

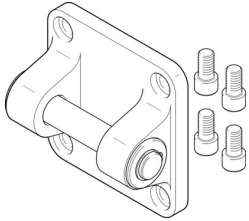

## Fisa de date

| Caracteristica                       | Valoare                                      |
|--------------------------------------|--|
| Dimensiune                           | 200  |
| Pe baza standardului                 | ISO 15552                                    |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS                   | VDMA24364-B2-L                               |
| Temperatura ambianta                 | -40 °C...90 °C                               |
| Greutate produs                      | 10020 g                                      |
| Nota privind materialele             | Conform RoHS                                 |
| Material fixare                      | Otel galvanizat                              |
| Material bolt                        | Otel galvanizat                              |
| Material mansona                     | Otel   |
| Material rulment                     | Material plastic                             |
| Material saiba                       | Otel galvanizat                              |
| Material suruburi                    | Otel, galvanizat                             |
| Material siguranta                   | Otel cu arc, galvanizat                      |