


## Set axial EAMM-A-P6-38A-57A

Numar piesa: 562645

**FESTO**

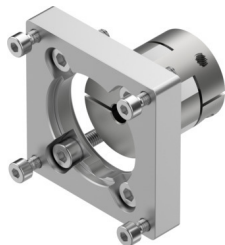

### Fisa de date

| Caracteristica                      | Valoare                |
|-------------------------------------|------------------------|
| Lungime nominala                    | 11 mm                  |
| Pozitie de instalare                | orice                  |
| Turatie max.                        | 8000 1/min             |
| Conformitatea LABS                  | VDMA24364-B2-L         |
| Temperatura de depozitare           | -25 °C...60 °C         |
| Umiditate relativa                  | 0 - 95 %               |
| Tip de protectie                    | IP40                   |
| Temperatura ambianta                | -10 °C...60 °C         |
| Momentul de inertie al masei        | 5.87 kgmm <sup>2</sup> |
| Cuplu transmisibil                  | 6.5 Nm                 |
| Greutate produs                     | 130 g                  |
| Cod de interfata actuator           | P6-38A                 |
| Codul interfetei motor In           | 57A                    |
| Cod de interfata carcasa de cuplare | 38A                    |
| Nota privind materialele            | Conform RoHS           |