 



Placa de capat VMPAL-EPL-SD9-IP40

Numar piesa: 570777

FESTO

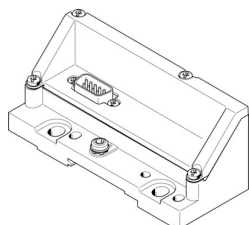

Fisa de date

Caracteristica	Valoare
Latime	43 mm
Lungime	107.3 mm
Numarul max. de pozitii de ventil	8
Ansamblu insula de ventile	Ventile cu dimensiuni cu posibilitate de combinare
Numar maxim de bobine de ventil	8
Presiune de lucru	-0.09 MPa...1 MPa -0.9 bar...10 bar
Presiunea de control	0.3 MPa...0.8 MPa 3 bar...8 bar
Tensiune nominala de functionare CC	24 V
Clasa de rezistenta la coroziune KBK	3 - stres intens de coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Tip de protectie	IP40
Nota privind tipul de protectie	in stare asamblata
Temperatura ambianta	-5 °C...50 °C
Greutate produs	190 g
Conector electric 1, functie	Multi-pin
Conexiune electrica 1, tip de conectare	Stecher
Conexiune electrica 1, tehnologie de conectare	Sub-D
Conexiune electrica 1, numar de pini/fire	9
Nota privind materialele	Conform RoHS
Material placa de capat	Aluminiu turnat sub presiune Ranforsat cu PA