


Stecker FBS-SCRJ-PP-GS

Numar piesa: 571017

FESTO

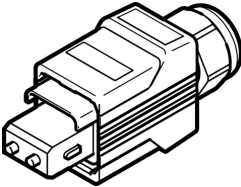

Fisa de date

Caracteristica	Valoare
Greutate produs	60 g
Nota privind interfata Fieldbus	PROFINET FO
Specificatie cablu Ethernet	Fibra optica Fibra polimerica 980/1000 µm Diametrul unui singur fir: 2,2 mm
Diametrul admisibil al cablului	6.5 mm...9.5 mm
Tip de protectie	IP65 IP67 conform IEC 60529
Temperatura ambianta	-40 °C...70 °C
Temperatura de depozitare	-40 °C...70 °C
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Material carcasa	Zinc turnat sub presiune nichelat
Material garnituri	NBR TPE