


Stecher
NECU-S1W9-C2-APB
Numar piesa: 574589

FESTO

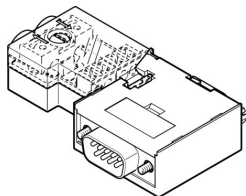

Fisa de date

Caracteristica	Valoare
Tipul de montare	4-40 UNC-2B
Greutate produs	57.48 g
Interfata Fieldbus	Sub-D, 9 pini, priza
Conexiune electrica 1	Stecher Sub-D, 9 pini
Conector electric 2	Terminal IDC
Rata baud	12 Mbit/s
Diametrul admisibil al cablului	8 mm 8 mm
Sectiune transversala a conectorului	0.08 mm ² ...0.5 mm ²
Tip de protectie	IP20
Temperatura ambianta	-20 °C...70 °C
Umiditate relativa	75 % la 25 °C
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Material carcasa	ranforsat PC