


Set paralel EAMM-U-50-S38-38AA-78

Numar piesa: 8058926

FESTO

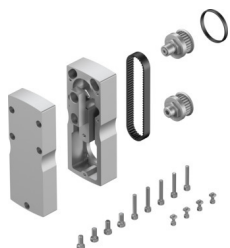

Fisa de date

Caracteristica	Valoare
Dimensiune	50
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	12.1 kgmm ²
Cuplu de antrenare in gol	0.01 Nm
Cuplu transmisibil	1 Nm
Greutate produs	600 g
Cod de interfata actuator	S38
Codul interfetei motor In	38AA
Nota privind materialele	Conform RoHS