


## Set axial EAMM-A-L27-57AA

Numar piesa: 8063449

**FESTO**

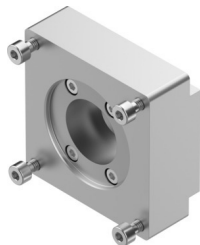

## Fisa de date

| Caracteristica               | Valoare                 |
|------------------------------|-------------------------|
| Lungime nominala             | 23.1 mm                 |
| Pozitie de instalare         | orice                   |
| Turatie max.                 | 10000 1/min             |
| Conformitatea LABS           | VDMA24364-B2-L          |
| Temperatura de depozitare    | -25 °C...60 °C          |
| Umiditate relativa           | 0 - 95 %                |
| Tip de protectie             | IP40                    |
| Temperatura ambianta         | -10 °C...60 °C          |
| Momentul de inertie al masei | 0.355 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 2 Nm                    |
| Greutate produs              | 217 g                   |
| Cod de interfata actuator    | L27                     |
| Codul interfetei motor In    | 57AA                    |
| Nota privind materialele     | Conform RoHS            |