


Set axial EAMM-A-L27-57AB

Numar piesa: 8063450

FESTO

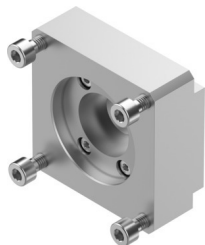

Fisa de date

Caracteristica	Valoare
Lungime nominala	23.1 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	0.355 kgmm ²
Cuplu transmisibil	1.6 Nm
Greutate produs	216 g
Cod de interfata actuator	L27
Codul interfetei motor In	57AB
Nota privind materialele	Conform RoHS