


## Set axial EAMM-A-L38-84AA

Numar piesa: 8063464

**FESTO**

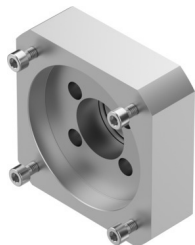

### Fisa de date

| Caracteristica               | Valoare               |
|------------------------------|-----------------------|
| Lungime nominala             | 45.9 mm               |
| Pozitie de instalare         | orice                 |
| Turatie max.                 | 8000 1/min            |
| Conformitatea LABS           | VDMA24364-B2-L        |
| Temperatura de depozitare    | -25 °C...60 °C        |
| Umiditate relativa           | 0 - 95 %              |
| Tip de protectie             | IP40                  |
| Temperatura ambianta         | -10 °C...60 °C        |
| Momentul de inertie al masei | 4.6 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 4.4 Nm                |
| Greutate produs              | 871 g                 |
| Cod de interfata actuator    | L38                   |
| Codul interfetei motor In    | 84AA                  |
| Nota privind materialele     | Conform RoHS          |