


Set axial EAMM-A-L48-70GA

Numar piesa: 8063483

FESTO

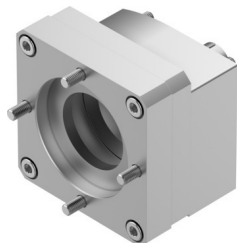

Fisa de date

Caracteristica	Valoare
Lungime nominala	53.3 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	14.5 kgmm ²
Cuplu transmisibil	12.5 Nm
Greutate produs	684 g
Cod de interfata actuator	L48
Codul interfetei motor In	70GA
Nota privind materialele	Conform RoHS