


Set axial EAMM-A-L62-70GA

Numar piesa: 8063499

FESTO

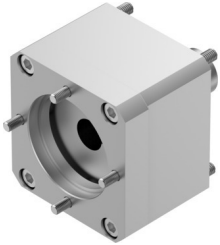

Fisa de date

| Caracteristica | Valoare |
|------------------------------|-----------------------|
| Lungime nominala | 56.4 mm |
| Pozitie de instalare | orice |
| Turatie max. | 5500 1/min |
| Conformitatea LABS | VDMA24364-B2-L |
| Temperatura de depozitare | -25 °C...60 °C |
| Umiditate relativa | 0 - 95 % |
| Tip de protectie | IP40 |
| Temperatura ambianta | -10 °C...60 °C |
| Momentul de inertie al masei | 151 kgmm ² |
| Cuplu transmisibil | 47 Nm |
| Greutate produs | 957 g |
| Cod de interfata actuator | L62 |
| Codul interfetei motor In | 70GA |
| Nota privind materialele | Conform RoHS |