


Set axial EAMM-A-L62-120GB

Numar piesa: 8063509

FESTO

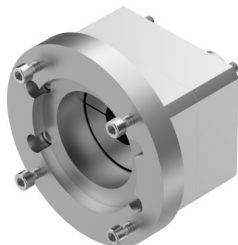

Fisa de date

Caracteristica	Valoare
Lungime nominala	71.9 mm
Pozitie de instalare	orice
Turatie max.	5500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	151 kgmm ²
Cuplu transmisibil	47 Nm
Greutate produs	1684 g
Cod de interfata actuator	L62
Codul interfetei motor In	120GB
Nota privind materialele	Conform RoHS