


Set axial EAMM-A-M43-70AA

Numar piesa: 8063535

FESTO

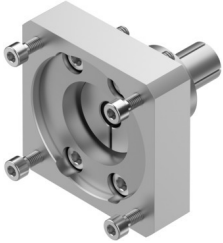

Fisa de date

Caracteristica	Valoare
Lungime nominala	27.9 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	14.5 kgmm ²
Cuplu transmisibil	12.5 Nm
Greutate produs	460 g
Cod de interfata actuator	M43
Codul interfetei motor In	70AA 70AB
Nota privind materialele	Conform RoHS