


## Set axial EAMM-A-M48-50GA

Numar piesa: 8063550

FESTO

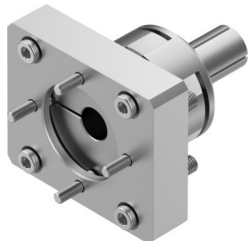

### Fisa de date

| Caracteristica               | Valoare              |
|------------------------------|----------------------|
| Lungime nominala             | 22.3 mm              |
| Pozitie de instalare         | orice                |
| Turatie max.                 | 6000 1/min           |
| Conformitatea LABS           | VDMA24364-B2-L       |
| Temperatura de depozitare    | -25 °C...60 °C       |
| Umiditate relativa           | 0 - 95 %             |
| Tip de protectie             | IP40                 |
| Temperatura ambianta         | -10 °C...60 °C       |
| Momentul de inertie al masei | 39 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 17 Nm                |
| Greutate produs              | 422 g                |
| Cod de interfata actuator    | M48                  |
| Codul interfetei motor In    | 50GA                 |
| Nota privind materialele     | Conform RoHS         |