


Set axial EAMM-A-M80-68GA

Numar piesa: 8063566

FESTO

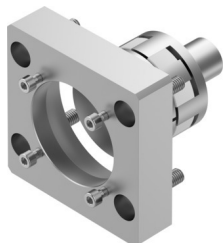

Fisa de date

Caracteristica	Valoare
Lungime nominala	26.5 mm
Pozitie de instalare	orice
Turatie max.	5500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	151 kgmm ²
Cuplu transmisibil	48 Nm
Greutate produs	911 g
Cod de interfata actuator	M80
Codul interfetei motor In	68GA
Nota privind materialele	Conform RoHS