
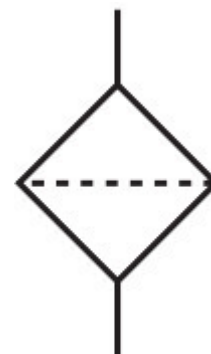


Filtru vacuum OAFF-G3-7

Numar piesa: 8068945

FESTO

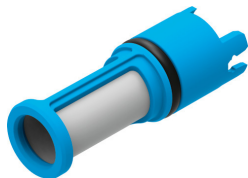

Fisa de date

Caracteristica	Valoare
Finete de filtrare	40 µm
Unitate de ambalare	10
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:::]
Conformitatea LABS	VDMA24364-B1/B2-L
Greutate produs	1.5 g
Tipul de montare	deplasabil cu blocare
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material filtru	Tesatura PA
Material carcasa	POM
Capacitate de impuls de cadere	0.7 MPa 7 bar 101.5 psi