


# Ventuza vacuum OGVM-30-G-N-G14F

Numar piesa: 8073848

FESTO

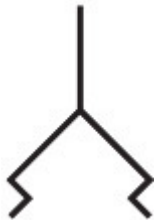

## Fisa de date

| Caracteristica                                   | Valoare                                                     |
|--------------------------------------------------|-------------------------------------------------------------|
| Ventuza de compensare a inaltimii                | 5 mm                                                        |
| Raza min. a piesei de prelucrat                  | 17.5 mm                                                     |
| Latimea nominala                                 | 3 mm                                                        |
| Diametrul ventuzei                               | 30 mm                                                       |
| Volum de aspiratie                               | 2.6 cm <sup>3</sup>                                         |
| Pozitie de conectare                             | sus                                                         |
| Pozitie de instalare                             | orice                                                       |
| Forma de ventuza                                 | rotund, in forma de clopot                                  |
| Presiune de lucru                                | -95 kPa...0 kPa<br>-0.95 bar...0 bar<br>-13.775 psi...0 psi |
| Presiunea nominala de functionare                | -60 kPa<br>-0.6 bar                                         |
| Mediu de operare                                 | aer atmosferic conform ISO 8573-1:2010 [7:-:-]              |
| Clasa de rezistenta la coroziune KBK             | 2 - Solicitare moderata din cauza coroziunii                |
| Conformitatea LABS                               | VDMA24364-A1-L                                              |
| Temperatura ambianta                             | -20 °C...80 °C                                              |
| Fora de mentinere la presiune de lucru nominala  | 32 N                                                        |
| Fora transversala la presiunea de lucru nominala | 62 N                                                        |
| Greutate produs                                  | 7 g                                                         |
| Tipul de montare                                 | prin racordul de vid                                        |
| Racord de vacuum                                 | Filet interior G1/4                                         |
| Culoare                                          | negru                                                       |
| Duritate Shore                                   | 60 +/- 5                                                    |
| Material pivot de insurubare                     | Aliaj de aluminiu forjat                                    |
| Nota privind materialele                         | Conform RoHS                                                |
| Material ventuze                                 | NBR                                                         |