


# Kit adaptare EHAM-E20-40-E8-35

Numar piesa: 8081015

FESTO

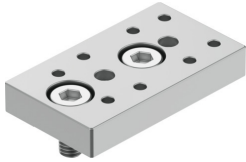

## Fisa de date

Caracteristica	Valoare
Dimensiune	40
Pozitie de instalare	orice
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364 zona III
Temperatura ambianta	-10 °C...70 °C
Greutate produs	24 g
Baza de codificare a interfetei	E20
Cod interfata structura	E8
Nota privind materialele	Conform RoHS
Material placa de adaptare	Aliaj de aluminiu forjat