


Set axial EAMM-A-T46-80PA

Numar piesa: 8091047

FESTO

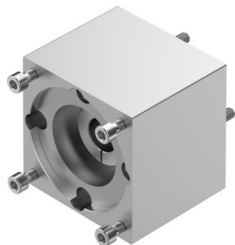

Fisa de date

Caracteristica	Valoare
Lungime nominala	68.5 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	7.65 kgmm²
Cuplu transmisibil	10 Nm
Greutate produs	917 g
Cod de interfata actuator	T46
Codul interfetei motor In	80PA 80RA
Nota privind materialele	Conform RoHS