


Set axial EAMM-A-V32-60PA

Numar piesa: 8091053

FESTO

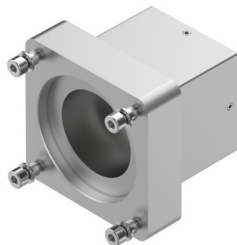

Fisa de date

Caracteristica	Valoare
Lungime nominala	55 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	1.03 kgmm ²
Cuplu transmisibil	1.5 Nm
Greutate produs	243 g
Cod de interfata actuator	V32
Codul interfetei motor In	60PA
Nota privind materialele	Conform RoHS