


Set paralel EAMM-U-60-S48-50GA-91

Numar piesa: 8105900

FESTO

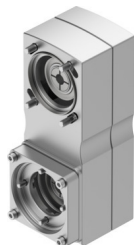

Fisa de date

Caracteristica	Valoare
Dimensiune	60
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	26.7 kgmm ²
Cuplu de antrenare in gol	0.07 Nm
Cuplu transmisibil	3 Nm
Greutate produs	1150 g
Cod de interfata actuator	S48
Codul interfetei motor In	50GA
Nota privind materialele	Conform RoHS