


Set axial
EAMM-A-P5-28B-40R

Numar piesa: 8107711

FESTO

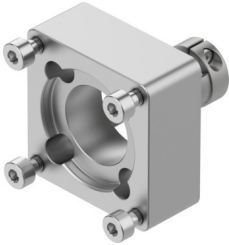

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	1.1 Nm
Greutate produs	71 g
Cod de interfata actuator	P5-28B
Codul interfetei motor In	40R
Nota privind materialele	Conform RoHS