


Set axial EAMM-A-D40-50GA

Numar piesa: 8117076

FESTO

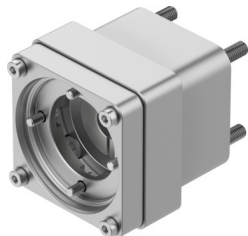

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	5.87 kgmm ²
Cuplu transmisibil	12.5 Nm
Greutate produs	411 g
Cod de interfata actuator	D40
Codul interfetei motor In	50GA
Nota privind materialele	Conform RoHS