


Ventil
VOFC-LT-M32C-MC-N14-FN
Numar piesa: 8122933

FESTO

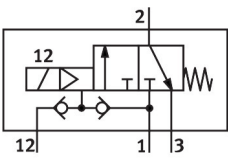

Fisa de date

Caracteristica	Valoare
Debit nominal standard (normalizat conform DIN 1343)	703 l/min
Presiune de lucru	0.1 MPa...0.8 MPa 1 bar...8 bar 14.5 psi...116 psi
Tip de protectie	IP65
Organizatia emitenta a certificatului	TÜV 968/V 1251.00/24
Funcție de siguranta	Ventilare sigura
Safety Integrity Level (SIL)	pana la SIL 3 mod de cerere ridicata pana la SIL 3 Mod de solicitare redusa
Indicatie referitoare la presiunea de lucru	0 - 0,8 MPa cu aer de control extern
Protectie la explozie	Zona 1 (ATEX) Zona 2 (ATEX) Zona 21 (ATEX) Zona 22 (ATEX)
Clasa de rezistenta la coroziune KBK	4 - Mediu coroziv deosebit de puternic
Conformitatea LABS	VDMA24364 zona III
Nota privind materialele	Conform RoHS