


Set paralel EAMM-U-60-D32-60RA-91

Numar piesa: 8123497

FESTO

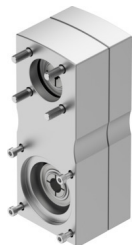

Fisa de date

Caracteristica	Valoare
Dimensiune	60
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	26.7 kgmm ²
Cuplu de antrenare in gol	0.07 Nm
Cuplu transmisibil	3 Nm
Greutate produs	1150 g
Cod de interfata actuator	D32
Codul interfetei motor In	60RA
Nota privind materialele	Conform RoHS