


Set axial EAMM-A-D80-150A-S1

Numar piesa: 8157274

FESTO

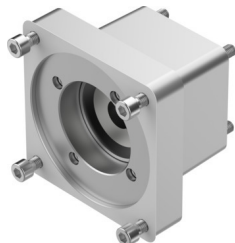

Fisa de date

Caracteristica	Valoare
Lungime nominala	103.5 mm
Pozitie de instalare	orice
Turatie max.	5500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	128 kgmm ²
Cuplu transmisibil	60 Nm
Greutate produs	3068 g
Cod de interfata actuator	D80
Codul interfetei motor In	140A 150A
Nota privind materialele	Conform RoHS