


## Set axial EAMM-A-N80-150A

Numar piesa: 8157277

**FESTO**

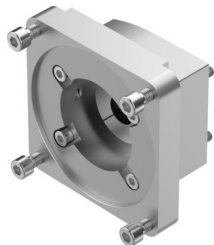

### Fisa de date

| Caracteristica               | Valoare               |
|------------------------------|-----------------------|
| Lungime nominala             | 72.5 mm               |
| Pozitie de instalare         | orice                 |
| Turatie max.                 | 5500 1/min            |
| Conformitatea LABS           | VDMA24364-B2-L        |
| Temperatura de depozitare    | -25 °C...60 °C        |
| Umiditate relativa           | 0 - 95 %              |
| Tip de protectie             | IP40                  |
| Temperatura ambianta         | -10 °C...60 °C        |
| Momentul de inertie al masei | 151 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 47 Nm                 |
| Greutate produs              | 2407 g                |
| Cod de interfata actuator    | N80                   |
| Codul interfetei motor In    | 140A<br>150A          |
| Nota privind materialele     | Conform RoHS          |