


Fixare senzor DASP-V4-8-A-R1

Numar piesa: 8174843

FESTO

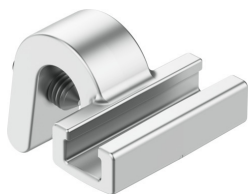

Fisa de date

Caracteristica	Valoare
Dimensiune	8
Design	pentru tirant
Pozitie de instalare	orice
pentru Ø piston	Ø32 Ø40 Ø50 Ø63
Clasa de rezistenta la coroziune KBK	4 - Mediu coroziv deosebit de puternic
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-20 °C...120 °C
Cuplu de strangere	0.6 Nm...1 Nm
Greutate produs	28 g
Tipul de montare	prinsa cu clema
Nota privind materialele	Conform RoHS
Suport material	Otel inoxidabil aliaj inalt
Material suruburi	otel inoxidabil inalt aliat